


# AVAGO Transceivers

Products may be RoHS compliant.  
Check mouser.com for RoHS status.



Opto Components

Avago

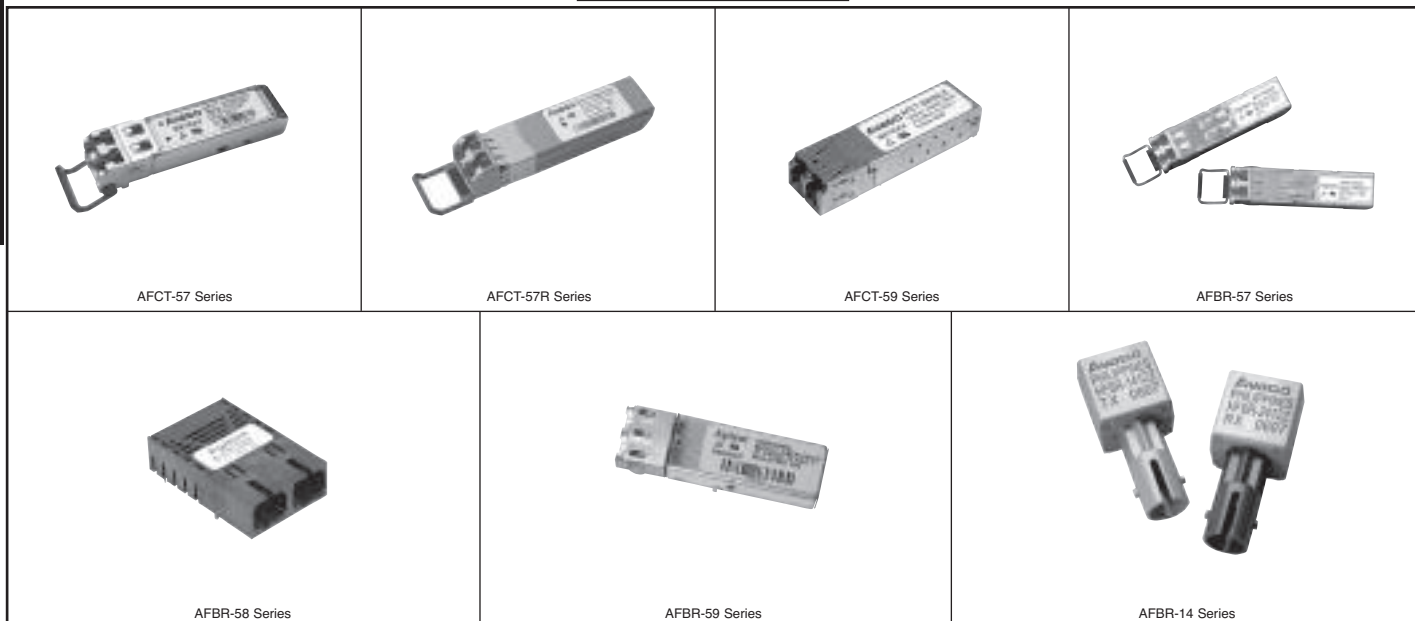

Avago Technologies is the world's leading provider of fiber optic transmitters, receivers and transceivers for Networking and Storage solutions. Avago Technologies offers unmatched quality with high-volume, low-cost manufacturing techniques.

## Fiber Optic Transceivers

Avago Technologies portfolio of optical transceivers include ATM/SONET, Ethernet, Storage, Parallel and WDM Transceivers

Avago Technologies is the leading supplier of fiber optic transceivers, with manufacturing and testing procedures that produce the industry's most reliable devices. Avago's broad portfolio of Ethernet, SONET and Fibre Channel transceivers supports all speeds and includes transmitters and receivers for industrial and automotive applications. The company's support and order fulfillment organizations provide unmatched service and delivery worldwide.

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Avago Part No.	Description	Data Rate	Fiber Type	Price Each			
					1	10	50	100
<a href="#">630-ABCU-5710RZ</a>	ABCU-5710RZ	Electrical Transceiver 1000BASE-T SFP RX_LOS Disabled	1.25 Gbd	Cat 5 Cable	84.66	76.50	71.40	66.30
<a href="#">630-HBCU-5710R</a>	HBCU-5710R	1000BASE-T Small Form Factor Pluggable Transceiver	1.25 Gbd	Cat 5 Cable	111.22	100.50	96.32	87.10
<a href="#">630-AFCT-5611Z</a>	AFCT-5611Z	GBIC Transceiver for Gigabit Ethernet	1.25 Gbd	Singlemode Fiber	147.20	142.60	138.00	133.40
<a href="#">630-AFCT-5710PZ</a>	AFCT-5710PZ	SMF Transceiver Gigabit Ethernet SFP Bail De-Latch	1.25 Gbd	Singlemode Fiber	76.80	74.40	72.00	69.60
<a href="#">630-AFCT-5715PZ</a>	AFCT-5715PZ	SMF Transceiver DMI-Gigabit Ethernet, SFP, Bail De-Latch	1.25 Gbd	Singlemode Fiber	80.00	77.50	74.50	71.50
<a href="#">630-AFCT-5745PZ</a>	AFCT-5745PZ	SFP Transceiver for SONET OC-48 and SDH/STM-16	2.75 Gbd	Singlemode Fiber	232.00	224.75	217.50	210.25
<a href="#">630-AFCT-5750PZ</a>	AFCT-5750PZ	SMF Transceiver ATM/SONET OC-12 SFP Bail De-Latch	622 Mbd	Singlemode Fiber	91.20	88.35	85.50	82.65
<a href="#">630-AFCT-5755PZ</a>	AFCT-5755PZ	SMF Transceiver DMI-ATM/SONET OC-12, SFP, Bail De-Latch	622 Mbd	Singlemode Fiber	91.20	88.35	85.50	82.65
<a href="#">630-AFCT-5760PZ</a>	AFCT-5760PZ	SMF Transceiver ATM/SONET OC-3 SFP Bail De-Latch	155 Mbd	Singlemode Fiber	76.80	74.40	72.00	69.60
<a href="#">630-AFCT-5760TPZ</a>	AFCT-5760TPZ	SMF Transceiver ATM/SONET OC-3 SFP Bail De-Latch	155 Mbd	Singlemode Fiber	91.20	88.35	85.50	82.65
<a href="#">630-AFCT-57R5APZ</a>	AFCT-57R5APZ	SMF Transceiver Fiber Channel/Storage Digital Diagnostic, SFP	4.25 Gbd	Singlemode Fiber	160.00	155.00	150.00	145.00
<a href="#">630-AFCT-57R5ATPZ</a>	AFCT-57R5ATPZ	SMF Transceiver with DMI for FC, SFP, Ext Temp -10 to +85°C	4.25 Gbd	Singlemode Fiber	288.00	279.00	270.00	261.00
<a href="#">630-AFCT-5805AZ</a>	AFCT-5805AZ	SMF Transceiver DMI-ATM/SONET OC-3 SFP Bail De-Latch	155 Mbd	Singlemode Fiber	89.70	86.89	84.09	81.29
<a href="#">630-AFCT-5805BZ</a>	AFCT-5805BZ	SMF Transceiver for ATM/SONET OC-3, 1x9, Black Case	155 Mbd	Singlemode Fiber	81.90	76.78	75.96	66.54
<a href="#">630-AFCT-5944TLZ</a>	AFCT-5944TLZ	SFF Transceiver for SONET OC-48/SDH STM-16 Multirate Operation	2.7 Gbd	Singlemode Fiber	306.72	297.14	287.55	277.97
<a href="#">630-AFCT-5961TLZ</a>	AFCT-5961TLZ	SMF Transceiver for ATM/SONET OC-3, 2x5	155 Mbd	Singlemode Fiber	110.40	106.95	103.50	100.05
<a href="#">630-AFBR-5103TZ</a>	AFBR-5103TZ	MMF Transceiver for ATM and Fast Ethernet Std Height	125 Mbd	Multimode Fiber	36.10	34.20	30.40	27.55
<a href="#">630-AFBR-5103Z</a>	AFBR-5103Z	MMF Transceiver ATM-Fast Ethernet Standard Height	125 Mbd	Multimode Fiber	36.10	34.20	30.40	27.55
<a href="#">630-AFBR-5205Z</a>	AFBR-5205Z	MMF Transceiver for ATM/SONET OC-3, 1x9	155 Mbd	Multimode Fiber	36.10	34.20	30.40	28.50
<a href="#">630-AFBR-5601Z</a>	AFBR-5601Z	GBIC Transceiver for Gigabit Ethernet	1.25 Gbd	Multimode Fiber	56.00	54.25	52.50	46.55
<a href="#">630-AFBR-5710PZ</a>	AFBR-5710PZ	MMF Transceiver for Gigabit Ethernet, SFP, Bail De-Latch	1.25 Gbd	Multimode Fiber	42.30	39.95	36.42	31.72
<a href="#">630-AFBR-5715LZ</a>	AFBR-5715LZ	SMF Transceiver DMI-Gigabit Ethernet SFP Std De-Latch	1.25 Gbd	Multimode Fiber	44.10	41.65	37.98	35.53
<a href="#">630-AFBR-5715PZ</a>	AFBR-5715PZ	MMF Transceiver DMIGigabit Ethernet, SFP, Bail De-Latch	1.25 Gbd	Multimode Fiber	44.10	41.65	37.98	35.53
<a href="#">630-AFBR-57R5AEZ</a>	AFBR-57R5AEZ	Fiber Channel-Shortwave, SFP, LC	1.25 Gbd	Multimode Fiber	49.05	46.33	42.24	36.78
<a href="#">630-AFBR-57R5APZ</a>	AFBR-57R5APZ	SFP Transceiver for Fiber Channel, Digital Diagnostic	1.25 Gbd	Multimode Fiber	49.05	46.33	42.24	36.78
<a href="#">630-AFBR-57R6AEZ</a>	AFBR-57R6AEZ	MMF Transceiver DMI/FC/GbE SFP, Quad Rate	4.25 Gbd	Multimode Fiber	45.60	44.18	42.75	41.33
<a href="#">630-AFBR-5803AZ</a>	AFBR-5803AZ	MMF Transceiver Fast Ethernet 100Base-FX /ATM/FDDI, 1x9	125 Mbd	Multimode Fiber	46.00	41.40	36.80	31.05
<a href="#">630-AFBR-5803TZ</a>	AFBR-5803TZ	MMF Transceiver Fast Ethernet 100Base-FX /ATM/FDDI	125 Mbd	Multimode Fiber	36.10	34.20	30.40	27.55
<a href="#">630-AFBR-5803Z</a>	AFBR-5803Z	MMF Transceiver for ATM and Fast Ethernet Std Height	125 Mbd	Multimode Fiber	36.10	34.20	30.40	27.55
<a href="#">630-AFBR-5805Z</a>	AFBR-5805Z	MMF Transceiver for ATM/SONET OC-3, 1x9	155 Mbd	Multimode Fiber	38.00	34.20	30.40	28.50
<a href="#">630-AFBR-5903AZ</a>	AFBR-5903AZ	MMF Transceiver for Fast Ether 100Base-FX/ATM/FDDI, 2x5	125 Mbd	Multimode Fiber	52.20	49.30	44.95	39.15
<a href="#">630-AFBR-5903EZ</a>	AFBR-5903EZ	MMF Transceiver Fast Ether 100Base-FX/ATM/FDDI, 2x5	125 Mbd	Multimode Fiber	46.80	44.20	40.30	37.70
<a href="#">630-AFBR-5903Z</a>	AFBR-5903Z	MMF Transceiver Fast Ethernet 100Base-FX /ATM/FDDI, 2x5	125 Mbd	Multimode Fiber	42.66	40.29	36.74	31.99
<a href="#">630-AFBR-5921ALZ</a>	AFBR-5921ALZ	MMF Transceiver for Fiber Channel/Storage, 2x5	2.125, 1.063 Gbd	Multimode Fiber	47.00	42.30	37.60	35.25
<a href="#">630-HFBR-5912EZ</a>	HFBR-5912EZ	MMF Transceiver for Gigabit Ethernet, 2x5	1.25 Gbd	Multimode Fiber	86.40	81.60	74.40	63.84
<a href="#">630-HFBR-5961ALZ</a>	HFBR-5961ALZ	MMF Transceiver Fast Ethernet/ATM/FDDI/SONET OC-3	155 Mbd	Multimode Fiber	61.60	55.44	49.28	44.66
<a href="#">630-HFBR-1402Z</a>	HFBR-1402Z	Transceiver Module Data Rate:115 KBPS, Standard SMA for Tx	160 Mbd	HCS	16.34	15.48	13.76	12.47
<a href="#">630-HFBR-1404Z</a>	HFBR-1404Z	Optical Transmitter for Industrial Applications, High Power, 2x4, SMA	80 KBs	HCS	16.34	15.48	13.76	12.47

