


HAMMOND Racks and Accessories



HAMMOND KNOCKDOWN RACKS

Features:

- Heavy duty 16 gauge steel top, bottom, and sides
- Rails are made of 10 gauge steel finished in Black Powder Paint
- Unit is shipped complete with 4 infinitely adjustable (front to back) combination rails
- Rails round hole punched for 10-32 screws
- Includes 4 leveling feet
- Shipped in a flat pack container for damage-free receipt
- Simple assembly using one bolt in each corner to lock the sides to the top and bottom

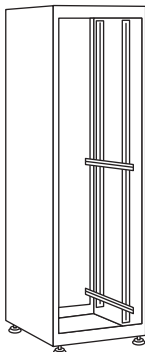

Overall Width: 21.34"
Panel Width: 19"
Panel Depth: 24.5"

"Shipped Factory Direct"


For quantities of 2 and up, call for quote.

MOUSER STOCK NO.				Dimensions: in.			Price Each
Textured Black		Textured Beige		H	Panel Height		
Mfr.	Mfr. Part No.	Mfr.	Mfr. Part No.		Inches	Units	
546—REFK1903524BK1	546—REFK1903524CG1	40.19	35.00	20	449.17		
546—REFK1904224BK1	546—REFK1904224CG1	47.19	42.00	24	483.03		
546—REFK1904924BK1	546—REFK1904924CG1	54.19	49.00	28	550.85		
546—REFK1905624BK1	546—REFK1905624CG1	61.19	56.00	32	584.73		
546—REFK1906324BK1	546—REFK1906324CG1	68.19	63.00	36	610.17		
546—REFK1907024BK1	546—REFK1907024CG1	75.19	70.00	40	677.97		
546—REFK1907724BK1	546—REFK1907724CG1	82.19	78.75	45	708.48		

HAMMOND DOORS FOR KNOCKDOWN RACKS

Features:

- Flush mount
- Features lockable latch and spring loaded pins for instant installation or removal
- Allows full access to space between panel rails when open
- Constructed from 18 gauge steel
- Finish matches "REFK" type rack in baked powder paint
- Solid door is reversible right or left opening (by inverting door)
- Louvered door opens right hand only with louvers facing down

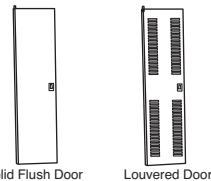

For quantities of 2 and up, call for quote.

MOUSER STOCK NO.				Dimensions: in.			Price Each
Textured Black		Textured Beige		Use With Rack Part Number	Panel Height		
Mfr.	Mfr. Part No.	Mfr.	Mfr. Part No.		Inches	Units	
546—RSDFF19035BK1	546—RSDFF19035CG1	REFK1903524	35.00	20	110.08		
546—RSDFF19042BK1	546—RSDFF19042CG1	REFK1904224	42.00	24	129.76		
546—RSDFF19049BK1	546—RSDFF19049CG1	REFK1904924	49.00	28	143.87		
546—RSDFF19056BK1	546—RSDFF19056CG1	REFK1905624	56.00	32	157.25		
546—RSDFF19063BK1	546—RSDFF19063CG1	REFK1906324	63.00	36	166.70		
546—RSDFF19070BK1	546—RSDFF19070CG1	REFK1907024	70.00	40	176.12		
546—RSDFF19077BK1	546—RSDFF19077CG1	REFK1907724	77.00	44	190.29		


For quantities of 2 and up, call for quote.

MOUSER STOCK NO.				Dimensions: in.			Price Each
Textured Black		Textured Beige		Use With Rack Part Number	Panel Height		
Mfr.	Mfr. Part No.	Mfr.	Mfr. Part No.		Inches	Units	
546—RSDL19035BK1	546—RSDL19035CG1	REFK1903524	35.00	20	124.81		
546—RSDL19042BK1	546—RSDL19042CG1	REFK1904224	42.00	24	142.61		
546—RSDL19049BK1	546—RSDL19049CG1	REFK1904924	49.00	28	160.49		
546—RSDL19056BK1	546—RSDL19056CG1	REFK1905624	56.00	32	175.77		
546—RSDL19063BK1	546—RSDL19063CG1	REFK1906324	63.00	36	191.04		
546—RSDL19070BK1	546—RSDL19070CG1	REFK1907024	70.00	40	203.78		
546—RSDL19077BK1	546—RSDL19077CG1	REFK1907724	77.00	44	216.54		

HAMMOND DESK TOP RACK (LIGHT DUTY)

Features:

 - 16 gauge steel 19" table top rack
- Rails are infinitely adjustable (front to back)
- Rails have round holes punched for 10-32 clip nuts
- Includes rubber feet, 2 lifting handles and 10-32 clip nuts
- Overall width: 21"
- Overall height: 2" over Panel Height




For quantities of 2 and up, call for quote.

MOUSER STOCK NO.				Panel Height: in.		Number of Clip Nuts	Price Each
Textured Black		Textured Beige		Inches	Units		
Mfr.	Mfr. Part No.	Mfr.	Mfr. Part No.				
13" Deep							
546—RCBS1900313BK1	546—RCBS1900313CG1	3.50	2	8	101.82		
546—RCBS1900513BK1	546—RCBS1900513CG1	5.25	3	8	109.57		
546—RCBS1900713BK1	546—RCBS1900713CG1	7.00	4	8	118.49		
546—RCBS1900813BK1	546—RCBS1900813CG1	8.75	5	16	134.24		
546—RCBS1901013BK1	546—RCBS1901013CG1	10.50	6	16	140.42		
546—RCBS1901213BK1	546—RCBS1901213CG1	12.25	7	16	152.75		
546—RCBS1901413BK1	546—RCBS1901413CG1	14.00	8	16	191.33		
17" Deep							
546—RCBS1900517BK1	546—RCBS1900517CG1	5.25	3	8	131.17		
546—RCBS1900717BK1	546—RCBS1900717CG1	7.00	4	8	152.75		
546—RCBS1900817BK1	546—RCBS1900817CG1	8.75	5	16	182.06		
546—RCBS1901017BK1	546—RCBS1901017CG1	10.50	6	16	192.87		
546—RCBS1901217BK1	546—RCBS1901217CG1	12.25	7	16	211.40		
546—RCBS1901417BK1	546—RCBS1901417CG1	14.00	8	16	216.00		

HAMMOND DESK TOP RACK (HEAVY DUTY)

Features:

- 16 gauge steel 19" table top rack
- Rails are fixed both front and rear
- Rails have round holes punched for 10-32 clip nuts
- Includes 2 pair of fixed accessory rails (for rear support of heavier equipment), rubber feet, 2 lifting handles and 10-32 clip nuts
- Overall width: 21"
- Overall height: 2" over Panel Height

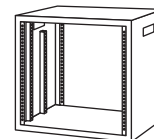


For quantities of 2 and up, call for quote.

MOUSER STOCK NO.				Panel Height: in.		Number of Clip Nuts	Price Each
Textured Black		Textured Beige		Inches	Units		
Mfr.	Mfr. Part No.	Mfr.	Mfr. Part No.				
17.5" Deep							
546—RCHS1900817BK1	546—RCHS1900817CG1	8.75	5	8	197.42		
546—RCHS1901017BK1	546—RCHS1901017CG1	10.50	6	16	228.31		
546—RCHS1901417BK1	546—RCHS1901417CG1	14.00	8	16	233.75		
546—RCHS1901717BK1	546—RCHS1901717CG1	17.50	10	16	242.72		
546—RCHS1902217BK1	546—RCHS1902217CG1	22.75	13	16	264.29		
546—RCHS1902817BK1	546—RCHS1902817CG1	28.00	16	16	310.64		
24.5" Deep							
546—RCHS1901024BK1	546—RCHS1901024CG1	10.50	6	16	307.43		
546—RCHS1901424BK1	546—RCHS1901424CG1	14.00	8	16	323.59		
546—RCHS1901724BK1	546—RCHS1901724CG1	17.50	10	16	334.39		
546—RCHS1902224BK1	546—RCHS1902224CG1	22.75	13	16	345.18		
546—RCHS1902824BK1	546—RCHS1902824CG1	28.00	16	16	359.53		

HAMMOND FIXED SHELF

Features:

- 14 gauge steel construction
- 19" rack mount shelf
- Side slotted for easy front to back adjustment
- Finished in Textured Black Powder Paint

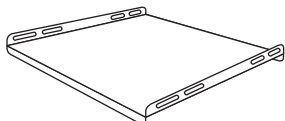


For quantities of 10 and up, call for quote.

MOUSER STOCK NO.	Hammond Part No.	Dimensions: in.		Price Each	
		H	D	1	2
Solid					
546-RFUS1918BK1	RFUS1918BK1	19.00	18.00	40.34	38.65
546-RFUS1921BK1	RFUS1921BK1	19.00	21.00	42.76	40.97
546-RFUS1926BK1	RFUS1926BK1	19.00	26.00	45.80	43.88
Vented					
546-RFVS1918BK1	RFVS1918BK1	19.00	18.00	40.34	38.65
546-RFVS1921BK1	RFVS1921BK1	19.00	21.00	42.76	40.97
546-RFVS1926BK1	RFVS1926BK1	19.00	26.00	45.80	43.88

HAMMOND FIXED/PULL-OUT SHELF

Features:

- 18 gauge steel construction
- Mounts to internal rails
- Finished in Smooth White
- 14 gauge brackets, side slotted for easy front to back adjustment

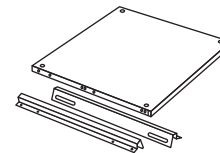

For quantities greater than 10, call for quote.

MOUSER STOCK NO.	Hammond Part No.	Dimensions: in.		Bracket Depth	Price Each		
		H	D		1	2	5
546-RASC1912WH2	RASC1912WH2	19.00	11.90	13.20	61.92	59.32	57.10
546-RASC1916WH2	RASC1916WH2	19.00	15.90	14.90	69.55	66.63	64.13
546-RASC1922WH2	RASC1922WH2	19.00	21.90	20.90	79.30	75.98	73.13

HAMMOND RAIL MOUNT STORAGE DRAWERS

For quantities greater than 10, call for quote.

MOUSER STOCK NO.	Hammond Part No.	MOUSER STOCK NO.	Hammond Part No.	Drawer Depth: in.	Price Each		
					1	2	5
Black Textured		Beige Textured					
546-RDRW1900312BK1	RDRW1900312BK1	546-RDRW1900312CG1	RDRW1900312CG1	12	174.62	167.30	161.02
546-RDRW1900316BK1	RDRW1900316BK1	546-RDRW1900316CG1	RDRW1900316CG1	16	189.88	181.92	175.10
546-RDRW1900322BK1	RDRW1900322BK1	546-RDRW1900322CG1	RDRW1900322CG1	22	198.61	190.29	183.15

Features:

- Plastic front pull handle
- Slides, hardware, lock and two keys included
- Weight load tested to 120 lbs.

